


# VersaBlade HT Wire-to-Wire Connectors >

VersaBlade HT wire-to-wire connectors deliver reliable signal and power transmission at 600V and 14.0A with superior mating reliability, polarization and easy harness assembly. High-temperature variants support -55 to +150°C, 600V/14.0A max. power requirements with robust positive-locking and Terminal Position Assurance (TPA) accessory for contact reliability. These connectors are Glow Wire capable to ensure the safety of home appliance users. Customers can use this connector in applications where high temperature tolerance is required.

Number of Circuits	Single-Row: 2, 3 Circuits Dual-Row: 4 Circuits
Pitch	6.20, 7.30mm
Wire Size(AWG)	14 – 24, 18+18, 18+20, 20+20, 22+22
Current Rating	14.0A
Flammability Rating	UL 94V-0
Glow-Wire Capable	Yes
Operating Temp	-55 to 150°C
TPA Option	Yes

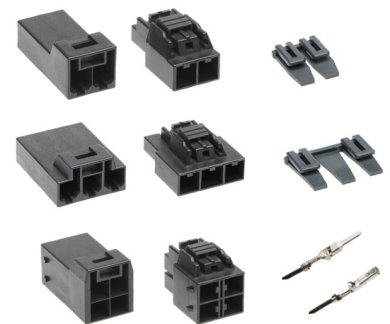

## ORDERING INFORMATION

Part Numbers	Description
217348-0200	Plug Housing 2 Circuits
217348-0300	Plug Housing 3 Circuits
217348-0400	Plug Housing 4 Circuits
217347-0200	Receptacle Housing 2 Circuits
217347-0300	Receptacle Housing 3 Circuits
217347-0400	Receptacle Housing 4 Circuits
217347-0290	TPA 2 Circuits
217347-0390	TPA 3 Circuits

Terminal PN	Description
217347-8000 (Male) 217348-8000 (Female)	14 16
217347-8100 (Male) 217348-8100 (Female)	18 20
217347-8400 (Male) 217348-8400 (Female)	22 24
217347-8200 (Male) 217348-8200 (Female)	18+18 18+20
217347-8300 (Male) 217348-8300 (Female)	20+20 22+22



SCAN FOR  
ADDITIONAL  
INFORMATION

[www.molex.com](http://www.molex.com)