


CABLE-TO-CABLE (REAR PANEL MOUNT)

MM - RUGGED METAL &

MN - RUGGED PLASTIC

0.050" | 9 THROUGH 100 CONTACTS

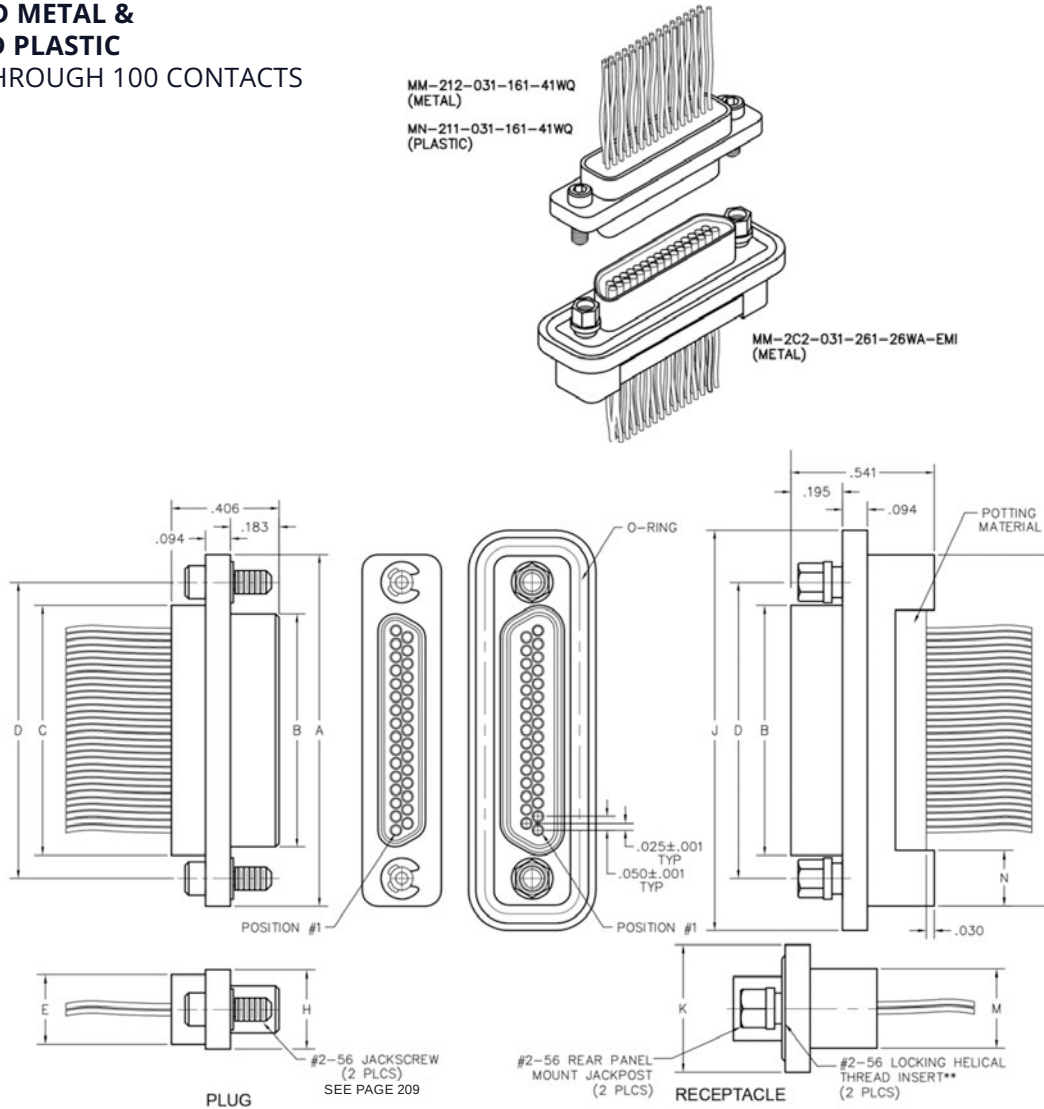

DIMENSIONS

Size	Contact Row	A	B		C	D	E	H	Hardware	J	K	L	M	N
			Plug MAX	RCPT MAX										
9	2	0.775	0.334	0.400	0.390	0.565	0.270	0.298	#2-56 UNC THD	0.957	0.480	0.773	0.298	0.210
15		0.925	0.484	0.550	0.540	0.715				1.107		0.923		
21		1.075	0.634	0.700	0.690	0.865				1.257		1.073		
25		1.175	0.734	0.800	0.790	0.965				1.357		1.173		
31		1.325	0.884	0.950	0.940	1.115				1.507		1.323		
37		1.475	1.034	1.100	1.090	1.265				1.657		1.473		
51	3	1.425	0.984	1.050	1.040	1.215	0.310	0.341	#4-40 UNC THD	1.657	0.523	1.477	0.440	0.239
69*		1.725	1.284	1.350	1.340	1.515				1.957		1.777		
100	4	2.160	1.384	1.508	1.432	1.800	0.360	0.384		2.383	0.600	2.219	0.515	0.301

* 69 Positon connectors are available in metal only.

** Shell accepts 0.200 Max #2-56 screw length (0.295 Max #4-40 screw length).

molex