



CABLE-TO-BOARD (REAR PANEL MOUNT)

MK – RUGGED BOARD MOUNT &
MM & MN – RUGGED CABLE
0.050" | 9 THROUGH 100 CONTACTS

MM-222-031-261-41WQ
(METAL)
MN-221-031-261-41WQ
(PLASTIC)

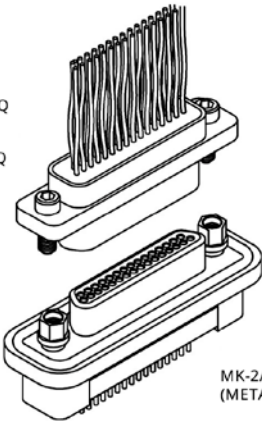

MK-2A2-031-135-2600-EMI
(METAL)

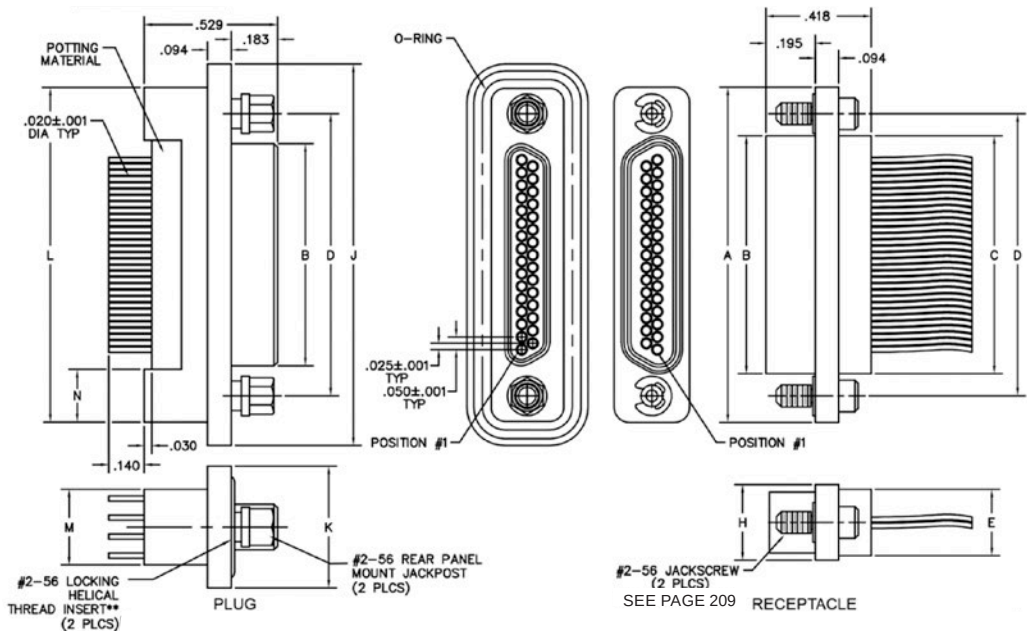

DIMENSIONS														
Size	Contact Row	A	B		C	D	E	H	Hardware	J	K	L	M	N
			Plug MAX	RCPT MAX			Potting Well MAX							
9	2	0.775	0.334	0.400	0.390	0.565	0.270	0.298	#2-56 UNC THD	0.957	0.480	0.773	0.298	0.210
15		0.925	0.484	0.550	0.540	0.715				1.107		0.923		
21		1.075	0.634	0.700	0.690	0.865				1.257		1.073		
25		1.175	0.734	0.800	0.790	0.965				1.357		1.173		
31		1.325	0.884	0.950	0.940	1.115				1.507		1.323		
37		1.475	1.034	1.100	1.090	1.265				1.657		1.473		
51	3	1.425	0.984	1.050	1.040	1.215	0.310	0.341	#4-40 UNC THD	1.657	0.523	1.477	0.440	0.239
69*		1.725	1.284	1.350	1.340	1.515				1.957		1.777		
100	4	2.160	1.384	1.508	1.432	1.800	0.360	0.384	#4-40 UNC THD	2.383	0.600	2.219	0.515	0.301

*69 Position connectors are available in metal only.
**Shell accepts 0.200 Max #2-56 screw length (0.295 Max #4-40 screw length).