


REAR PANEL MOUNT, RIGHT-ANGLE BOARD MOUNT

MK
0.050" | 9 THROUGH 100 CONTACTS

MATING MATRIX	
Connector	Mates With
MK-2D...	MK, ML, MM, MN receptacles
MK-2E...	MK, ML, MM, MN plugs

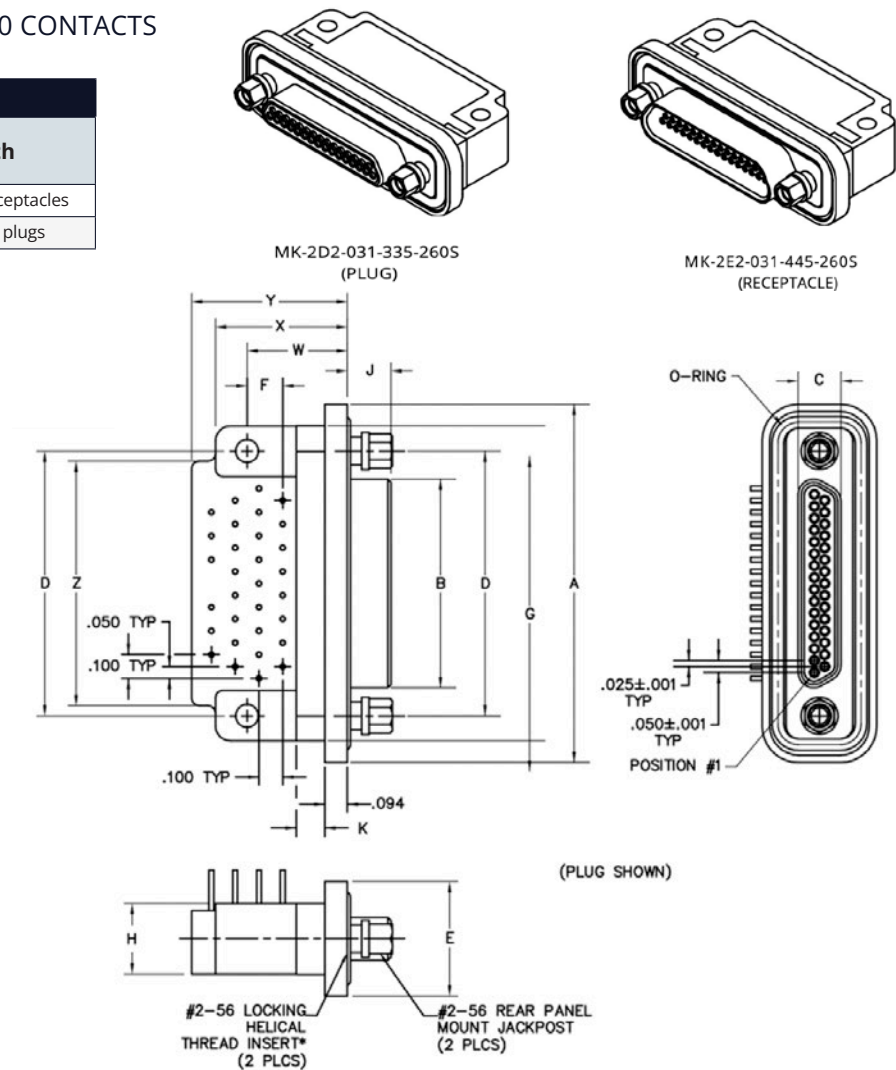

DIMENSIONS																				
Size	Contact Row	A	B		C		D	E	F	G	H	J		K	W	X MAX	Y MAX	Z	Hardware	Mounting Hole
			Plug MAX	RCPT MAX	Plug MAX	RCPT MAX						Plug	RCPT							
9	2	0.957	0.334	0.400	0.185	0.251	0.565	0.480	0.020	0.775	0.298	0.183	0.195	0.120	0.421	0.560	0.540	0.775	#2-56 UNC THD	0.096 DIA or #2-56 UNC Threaded Insert
15		1.107	0.484	0.550			0.715		0.150	0.925							0.660	0.925		
21		1.257	0.634	0.700			0.865			1.075							0.770	1.075		
25		1.357	0.734	0.800			0.965			1.175								1.175		
31		1.507	0.884	0.950			1.115			1.325								1.030		
37		1.657	1.034	1.100			1.265			1.475								1.180		
51	3	1.657	0.984	1.050	0.228	0.294	1.215	0.523	0.150	1.425	0.341					0.550	0.770	1.220	#4-40 UNC THD	0.125 DIA or #4-40 UNC Threaded Insert
69		1.957	1.284	1.350			1.515			1.725							0.870	1.450		
100	4	2.383	1.384	1.508	0.271	0.394	1.800	0.600	0.200	2.160	0.381			0.176	0.577	0.775	1.180	1.180	#4-40 UNC THD	0.125 DIA or #4-40 UNC Threaded Insert

**Shell accepts 0.200 Max #2-56 screw length (0.295 Max #4-40 screw length).

