

LEAD CONFIGURATION OPTIONS

RUGGED: MM-242-031-000-4100
XX-XXX-XXX-XXX-XXXX-XXX

SERIES	
MM .050" Rugged Metal Backshell	
BODY	
2	2-Row (Sizes 9 thru 51)
3	3-Row (Sizes 51 & 69)
4	4-Row (Size 100)
BODY STYLE:	
4	45°, one piece
6	45°, two piece **
BODY MATERIAL:	
2	Aluminum, with electroless nickel plating
3	Aluminum, with electrodeposited cadmium ☒
4	Aluminum, with hard anodized black plating
SIZE	
XXX 009, 015, 021, 025, 031, 037, 051, 069, 100	
CONTACTS	
TYPE CONTACTS/TERMINATIONS:	
000	None
HARDWARE	
STYLE OF HARDWARE:	
00	None
22	Two fixed jacknut assemblies (62*)
41	Two turning jackscrews, allen head, retaining ring (81*)
43	Two turning jackscrews, slot head, retaining ring (83*)
POLARIZATION / WIRING:	
00	None
OPTIONS	
0FZ Required for receptacles with grounding fingers when ordering hardware styles 41, 43, 81, & 83	


* = Use number in parenthesis when ordering size 100.

** = Sizes 9 and 15 not recommended for solder cup applications.

Stainless steel micro band for shield termination - AirBorn part number CDG10026

Band-it application tool - AirBorn part number CDG10027

☒ = Option not RoHS compliant

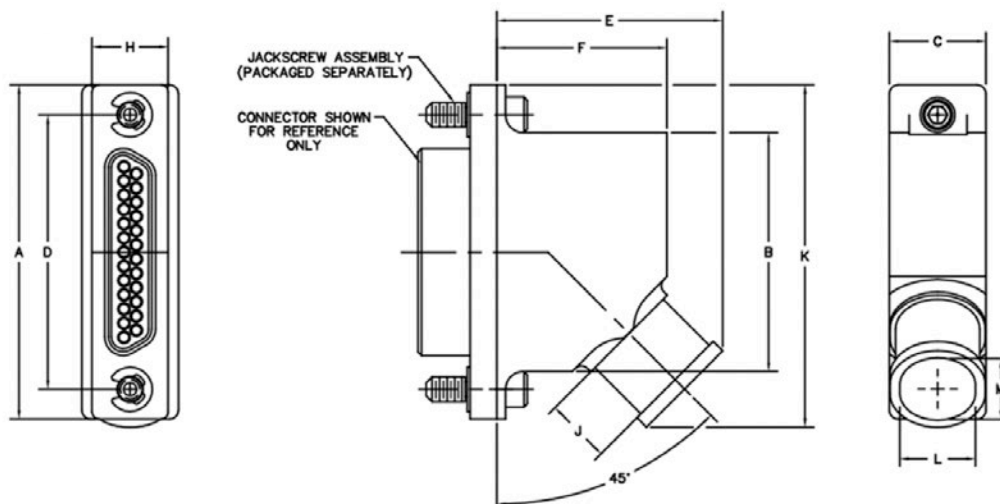

molex