

PLUG: WGR 92 PR9 SYCL
RECEPTACLE: WGR 92 SAD11 SYL
XXX XX XXXXX XXXX

PLUG

RECEPTACLE

SERIES	
WGR Plug, right angle, without mounting ears	WGR Receptacle, straight, without mounting ears
SIZE	
92 Number of contacts	92 Number of contacts
CONTACTS	

- When pin contacts are used, standard hardware orientation places the female hardware next to the #1 pin contact.
- When socket contacts are used, standard hardware orientation places the male hardware next to the #1 socket contact.

TYPE CONTACTS/TERMINATIONS:

PR7 Pin, right angle, dip solder, .109" x .025" dia
PR9 Pin, right angle, dip solder, .140" x .025" dia
PR11 Pin, right angle, dip solder, .172" x .025" dia

TYPE CONTACTS/TERMINATIONS:

SAC Socket, straight, solder cup (.035" I.D.)
SAD7 Socket, straight, dip solder, .109" x .027" dia
SAD9 Socket, straight, dip solder, .140" x .027" dia
SAD11 Socket, straight, dip solder, .172" x .027" dia
SAD16 Socket, straight, dip solder, .250" x .027" dia
SAG7 Socket, straight, dip solder, .109" x .018" dia
SAG9 Socket, straight, dip solder, .140" x .018" dia
SAG11 Socket, straight, dip solder, .172" x .018" dia
SAP Socket, straight, pin termination .150", connector saver
SAW40 Socket, straight, wire wrap®, .625"
SAF6 Socket, straight, flex circuit, .093"


HARDWARE

SYCL Guide set, cross hole mount
JCL Fixed jackset, cross hole mount


SYL Guide set, long
JT Turning jackset, .460"
JTA Turning jackset, .160"

OPTIONS


- Option Codes: Add to the end of the part number. Example: WGR92PR9JCL-D01. Call factory for additional codes.
 - D01 Pretinned contact terminations (except solder cups, wire wraps® and flex contacts) with 63/37 or 60/40 solder. ☒
 - P39 Pretinned contact terminations (except solder cups, wire wraps® and flex contacts) with SAC305 solder (lead free).
- ☒ = Option not RoHS compliant

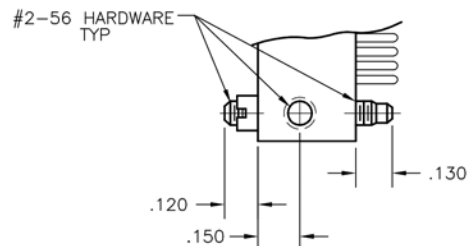

EXAMPLE: -JCL HARDWARE (PLUG)

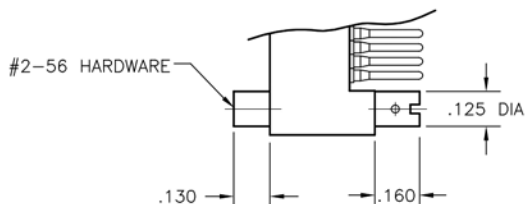

EXAMPLE: -JTA HARDWARE (RECEPTACLE)

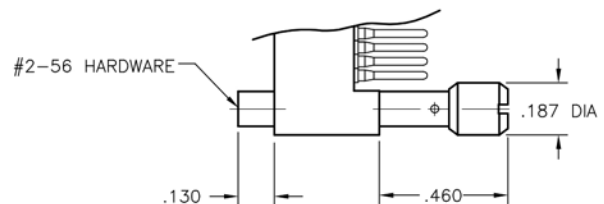

EXAMPLE: -JT HARDWARE (RECEPTACLE)